

Cordless Systems

Hilti. Outperform. Outlast.





Cordless Rotary Hammers

Cordless rotary hammer TE 2-A22	Page 56, 58
Cordless rotary hammer TE 4-A22	Page 57-58
Cordless rotary hammer TE 6-A36-AVR	Page 57-58



Drills, Impact Drivers and Wrenches

Cordless drill driver SF 2-A	Page 59
Cordless compact drill driver SFC 22-A	Page 60
Cordless hammer drill driver SFH 22-A	Page 60, 64
Cordless impact wrench SIW 22-A	Page 61, 64
Cordless impact wrench SIW 22T-A 1/2"	Page 61, 64
Cordless compact drill driver SFC 14-A	Page 62, 63
Cordless impact wrench SIW 14-A	Page 62, 63



Inserts

HSS bit sets (metric) HSS sets	Page 64
Bits metric HSS	Page 64-65
HSS cobalt bits (metric) HSS Co	Page 65-66
MultiCut bimetal hole saw HS-MU	Page 66-67
MultiCut bimetal hole saw adaptor and accessories HS-MU	Page 67
MetalCut bimetal hole saw HS-ME	Page 67-68
MetalCut bimetal adaptor and accessories HS-ME	Page 68
Stepper bit HSS SB	Page 68
Spade bit WDB S	Page 68
Spade bit accessories WDB S	Page 69
Auger bit WDB A	Page 69
Torsion bit sets S-BS (T)	Page 69
System screwdriver bits S-SY B	Page 69
Torsion screwdriver bits S-B (T)	Page 70
Magnetic bit holder S-BH (M)	Page 70
Quick-change bit holder S-BH (QC)	Page 70
Socket S-NS (C)	Page 70



Cordless Combihammers

Cordless combihammer TE 30-A36	Page 71
--------------------------------	---------



Cordless Saws

Cordless reciprocating saw WSR 22-A	Page 72
Cordless reciprocating saw WSR 36-A	Page 72
Cordless circular saw for cutting metal SCM 22-A	Page 73
Cordless circular saw SCW 22-A	Page 73



Cordless Angle Grinders

Cordless angle grinder AG 125-A22	Page 74
-----------------------------------	---------



Cordless Dispensers

Cordless electric dispenser HDE 500-A22	Page 75
---	---------

Go above and beyond

CORDLESS SYSTEMS FOR TOTAL MOBILITY.

Take advantage of one of the most advanced lithium-ion battery technologies on the market today – Hilti Lithium CPS batteries, chargers and tools are designed down to the last detail for superior power and performance with unmatched durability.



Mobility at its best. Strong and reliable.

Rise to new heights. Go further without stops. Experience new-found freedom. It's not the pressure of time that makes your pulse race, but the breathtaking handling and virtually unlimited performance of a new generation of tools – Hilti cordless systems for total mobility.

Hilti cordless tools featuring Lithium Cordless Power Care (CPC) open up new horizons that mean uncompromising reliability with greatest possible independence from power outlets.



High Flyers!

Be sure to fasten your seat belt: at 2.7 kg the new TE 2-A cordless rotary hammer brings cordless freedom to all trades while the SCM 22-A cordless circular saw gives you sparkless, straight and fast cuts in metal!






Mobility at its best.

Hilti Lithium CPC wins hands down.

Advantages of Lithium-ion

- More work per battery charge - up to 100% higher capacity than NiCd/NiMH batteries of the same weight
- Ready to use in no time - very fast initial charge to 75% capacity
- Less weight- only half the weight of NiCd/NiMH batteries of the same capacity
- No self-discharge - batteries do not lose their charge during storage and are ready to use at any time
- Environmentally friendly - in contrast to NiCd batteries, no pollution by heavy metals
- Additional overload sensors to protect the motor and electronics

Unique to Hilti lithium CPC.

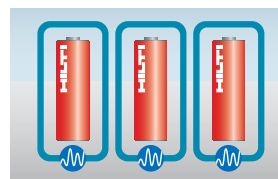


Individual cell voltage control

The Hilti Lithium CPC system monitors each cell electronically, which is essential for long battery life.



Long-life cells

The rugged cells in these Hilti batteries guarantee a higher number of charging cycles and thus longer total battery lifetime.

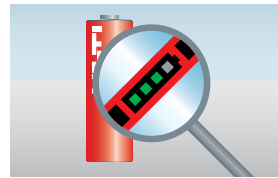

State-of-charge and warning LEDs

Hilti Lithium CPC batteries feature an LED charge status display. You can therefore check the level of the "fuel tank" at any time.



Glass-fibre reinforced

Exceptionally ruggedly built to withstand the harsh conditions of everyday jobsite use, Hilti Lithium CPC batteries and tools feature tough fibreglass-reinforced casings with rubber grip areas.

Voltages that meet your requirements perfectly.

12, 14, 22 and 36 volts – all with one charger.

Hilti Lithium CPC batteries, tools and chargers incorporate one of the most advanced lithium-ion battery technologies available today. Designed down to the last detail for maximum performance and capacity, these cordless tool systems are also built to last.



12 volt B 12/2.6 Li-ion



SFC 14-A cordless compact drill / driver

14 volt B 14 1.6 Li-ion / B 14 3.3 Li-ion



SFC 14-A cordless compact drill / driver



SIW 14-A cordless impact wrench



SFL 14-A cordless lamp

22 volt B 22 1.6 Li-ion / B 22 3.3 Li-ion



TE 4-A22 cordless rotary hammer



SCM 22-A cordless metal cutting saw



SFH 22-A cordless hammer drill driver



SIW 22T-A cordless impact wrench



AG 125-A22 cordless angle grinder



TE 2-A22 cordless rotary hammer



WSR 22-A cordless reciprocating saw



SCW 22-A cordless circular saw

36 Volt B 36 3.0 Li-ion / B 36 3.9 Li-ion



TE 6-A36-AVR cordless rotary hammer



WSR 36-A cordless reciprocating saw



WSC 70-A36 cordless circular saw



TE 30-A36 cordless combihammer

Make it fit.

Choose the right tools and accessories for your needs.



Make it fit.

Now you can select only the items you really need. Buy the tool without a battery or buy batteries and chargers separately. Exactly as you please, exactly to meet your needs.

Choose your combination from 3 different product categories.

Category 1: Standard single tool combo

Buy the tool in a standard set (with 2 batteries and a charger in a toolbox).



Tool case

+



Battery

+



Charger

Category 2: Individual items

Choose individual items to suit your needs.



Tool

and/or



Battery

and/or



Charger

Category 3: Custom tool kits

Combine 2 or more tools in one package according to your needs.



Tool

+



Battery

+



Charger

=



Combo Toolkit



or Soft bag



Cordless rotary hammer TE 2-A22



Key applications and advantages

- Construction: light-duty drilling in concrete and masonry
- Interior finishing: installing partition walls and suspended ceilings
- Metal fabricators: fastening metal items such as handrails, staircases, sun blinds, barriers, etc.
- Cordless freedom with the performance of a corded tool
- Compact size and light weight for superior handling

Technical data

Rated voltage	21.6 V
Battery type	Li-ion
Single impact energy	1.5 J
Full hammering frequency	5040 impacts/minute
Working mode	Hammer drilling, Drilling only
Drilling diameter range for hammer drill bits	4 - 16 mm
Optimum drilling diameter in concrete - max.	12 mm
Weight according to EPTA Procedure 01/2003	2.7 kg



CPC



Ordering designation	Package contents	Sales pack quantity	Item number
Kit TE 2-A22 + B 22/3.3 cas	1x Cordless rotary hammer TE 2-A22 assy, 1x Case, 1x Battery pack B 22/3.3 Li-Ion, 1x Battery charger C 4/36-90 110V	1 pc	2094052
Kit TE 2-A22 + B 22/3.3 cas	1x Cordless rotary hammer TE 2-A22 assy, 1x Case, 1x Battery pack B 22/3.3 Li-Ion, 1x Battery charger C 4/36-90 230V	1 pc	2093908
TE 2-A22 cas	1x Cordless rotary hammer TE 2-A22 assy, 1x Case	1 pc	2021420
TE 2-A22 cas	1x Cordless rotary hammer TE 2-A22 assy, 1x Case	1 pc	2034358



Cordless rotary hammer TE 4-A22



Key applications and advantages

- Drilling and hammer drilling in concrete and masonry
- Occasional drilling in wood and steel with optional chuck adapter
- Screwdriving using the special bit holder with TE-C (SDS Plus) connection end
- Ergonomically designed D-grip for comfortable use over long periods
- Robustly built and superbly engineered for cordless optimization

Technical data

Rated voltage	21.6 V
Battery type	Li-ion
Single impact energy	2 J
Full hammering frequency	5200 impacts/minute
Working mode	Hammer drilling, Drilling only
Drilling diameter range for hammer drill bits	5 - 16 mm
Optimum drilling diameter in concrete - max.	12 mm
Drilling diameter range for metal drill bits	3 - 10 mm
Weight according to EPTA Procedure 01/2003	3.3 kg



Ordering designation	Package contents	Sales pack quantity	Item number
TE 4-A22 cas	1x Cordless rotary hammer TE 4-A22, 1x Case	1 pc	410717

Cordless rotary hammer TE 6-A36-AVR



Key applications and advantages

- Drilling and hammer drilling in concrete and masonry
- Occasional drilling in wood and steel with optional quick-release chuck
- Screwdriving using the special bit holder with TE-C (SDS Plus) connection end
- Ergonomically designed D-grip for comfortable use over long periods
- Robustly built and superbly engineered for cordless optimization















Technical data

Rated voltage	36 V
Battery type	Li-ion
Single impact energy	2 J
Full hammering frequency	5283 impacts/minute
Working mode	Hammer drilling, Drilling only
Drilling diameter range for hammer drill bits	4 - 20 mm
Optimum drilling diameter in concrete - max.	16 mm
Drilling diameter range for metal drill bits	3 - 13 mm
Weight according to EPTA Procedure 01/2003	4 kg



Ordering designation	Package contents	Sales pack quantity	Item number
Kit TE 6-A36-AVR + B 36/3.0 cas	1x Cordless rotary hammer TE 6-A36-AVR assy, 1x Case, 1x Battery pack B 36/3.0 Li-Ion, 1x Battery charger C 4/36-350 110V	1 pc	2094050
Kit TE 6-A36-AVR + B 36/3.0 cas	1x Cordless rotary hammer TE 6-A36-AVR assy, 1x Case, 1x Battery pack B 36/3.0 Li-Ion, 1x Battery charger C 4/36-350 230V	1 pc	2093906
TE 6-A36-AVR cas	1x Cordless rotary hammer TE 6-A36-AVR assy, 1x Case	1 pc	2040910

Accessories for Cordless Rotary Hammers

Ordering designation		TE 2-A22	TE 6-A36-AVR	TE 4-A22	Sales pack quantity	Item number
Battery charger C 4/36-350 110V box		■	■	■	1 pc	2028992
Battery charger C 4/36-350 230V box		■	■	■	1 pc	2028876
Battery charger C 4/36-90 110V box		■			1 pc	2015763
Battery charger C 4/36-90 230V box		■			1 pc	2015762
Battery charger C 4/36-90 230V box		■			1 pc	2015761
Battery pack B 22/1.6 Li-Ion		■			1 pc	426177
Battery pack B 22/3.3 Li-Ion		■		■	1 pc	2007431
Battery pack B 36/3.0 Li-Ion			■		1 pc	418009
Dust removal system TE DRS-6-A cas			■		1 pc	410740
Goggles PP EY-HA R HC/AF clear Lens: PC material, thickness 2.2 mm, Supravision HC-AF coating, filter 2-1.2, impact energy 120m/s, surface resistance to fine particles: K, antifog: N				■	1 pc	2065591
Goggles PP EY-HA S clear Lens: PC material, thickness 2.1 mm, Supravision Extreme coating, filter: 2-1.2, impact energy: 120m/s, surface resistance to fine particles: K, antifog: N				■	1 pc	2065590
Safety glasses PP EY-CA NCH clear Lens: PC material, thickness 2.1 mm, Optidur NCH coating, filter: 2C-1.2, impact energy: 45m/s				■	1 pc	2065449
Safety glasses PP EY-GU B AF blue Lens: PC material, thickness 2.1 mm, Supravision HC-AF coating, filter: 2C-1.2, impact energy: 45m/s, surface resistance to fine particles: K, antifog: N				■	1 pc	2065447
Safety glasses PP EY-GU C HC/AF clear Lens: PC material, thickness 2.1 mm, Supravision HC-AF coating, filter: 2C-1.2, impact energy: 45m/s, surface resistance to fine particles: K, antifog: N				■	1 pc	2065445
Safety glasses PP EY-GU G HC/AF grey Lens: PC material, thickness 2.1 mm, Supravision HC-AF coating, filter: 2C-1.2, impact energy: 45m/s, surface resistance to fine particles: K, antifog: N				■	1 pc	2065446



Cordless drill driver SF 2-A



- Key applications and advantages**
- Driving self-tapping screws up to 4.8 mm diameter in metal
 - Driving screws up to 6 mm diameter in wood
 - Drilling with HSS bits up to 8 mm diameter in metal
 - Ergonomic grip and perfect balance for maximum working comfort
 - High productivity thanks to a drilling speed of up to 1,500 /min

Technical data	
Reversing switch	Yes
Battery capacity	2.6 Ah
Battery type	Li-ion
Bit diameter range steel twist - max.	6 mm
Rotation speed gear 1 under no load	400 rpm
Rotation speed gear 2 under no load	1500 rpm
Max. torque (soft joint)	12 Nm
Max. torque hard joint	24 Nm
Torque increments	15
Dimensions (LxWxH)	178 x 70 x 206 mm

Ordering designation	Package contents	Sales pack quantity	Item number
SF 2-A box	1x Cordless drill driver SF 2-A assy	1 pc	2090915
SF 2-A cas	1x Cordless drill driver SF 2-A assy, 1x Case	1 pc	2090912



Cordless compact drill driver SFC 22-A



CPC

Key applications and advantages

- Hole sawing in diameters up to 82 mm
- Driving screws up to 8 mm dia. in wood
- Drilling with auger & spade bits up to 26 mm dia. in wood
- Lightweight and compact
- Ergonomically designed grip for maximum working comfort

Technical data

Reversing switch	Yes
Battery capacity	1.6 Ah
Battery type	Li-ion
Rotation speed gear 1 under no load	600 rpm
Rotation speed gear 2 under no load	1800 rpm
Max. torque (soft joint)	28 Nm
Max. torque hard joint	55 Nm
Torque increments	15
Dimensions (LxWxH)	202 x 92 x 234 mm
Weight according to EPTA Procedure 01/2003	1.7 kg

Ordering designation	Package contents	Sales pack quantity	Item number
SFC 22-A box	1x Cordl. compact drill driver SFC 22-A CE	1 pc	2072955
SFC 22-A cas	1x Cordl. compact drill driver SFC 22-A CE, 1x Case	1 pc	2072954

Cordless hammer drill driver SFH 22-A



CPC

Key applications and advantages

- Hammer drilling in diameters up to 14 mm in brick, masonry, sand-lime block and aerated concrete
- Drilling with auger and spade bits up to 32 mm dia. in wood
- Drilling with high torque and speed in diameters up to 13 mm in metal
- Unbeaten performance and battery capacity in the 22 volt class
- Best performance-to-size ratio

Technical data

Rated voltage	21.6 V
Reversing switch	Yes
Battery capacity	3.3 Ah
Battery type	Li-ion
Rotation speed gear 1 under no load	370 rpm
Rotation speed gear 2 under no load	1250 rpm
Rotation speed gear 3 under no load	2140 rpm
Full hammering frequency	39000 impacts/minute
Max. torque (soft joint)	50 Nm
Max. torque hard joint	84 Nm

Ordering designation	Package contents	Sales pack quantity	Item number
SFH 22-A cas	1x Cordl. ham. dr. driver SFH 22-A CE/JP, 1x Case	1 pc	290211



Cordless impact wrench SIW 22-A



Key applications and advantages

- Tightening and releasing high-strength nuts and bolts from M6 to M12
- Setting HSA stud anchors in the sizes M8 to M12 with the S-TB torque bar
- Driving 6 mm and 8 mm HUS3 screw anchors in concrete
- Brushless motor for long lifetime and more work per charge
- Compact design allows easy use in tight corners and wherever space is limited

Technical data

Rated voltage	21.6 V
Reversing switch	Yes
Battery capacity	1.6 Ah
Battery type	Li-ion
Max. torque, setting 1	90 Nm
Max. torque, setting 2	135 Nm
Max. torque, setting 3	200 Nm
Full hammering frequency	3500 impacts/minute
Torque increments	3
Dimensions (LxWxH)	154 x 94 x 228 mm

Ordering designation	Package contents	Sales pack quantity	Item number
SIW 22-A 1/2" cas	1x Cordl. impact wrench SIW 22-A 1/2", 1x Case	1 pc	2006081

Cordless impact wrench SIW 22T-A 1/2"



Key applications and advantages

- Driving HUS3 screw anchors from 8 mm to 14 mm in diameter into concrete
- Tightening and releasing nuts and bolts from M12 to M24
- Assembling steel profiles, timber or pre-cast concrete components
- Compact design with excellent balance for precise handling
- 1/2" square drive with heavy-duty ball-notch retention for security and quick socket changing

Technical data

Rated voltage	21.6 V
Reversing switch	Yes
Battery capacity	3.3 Ah
Battery type	B 22/2.6 Li-ion
Max. torque, setting 1	450 Nm
Full hammering frequency	2500 impacts/minute
Dimensions (LxWxH)	232 x 94 x 258 mm
Weight according to EPTA Procedure 01/2003	3 kg
Chuck functionality	Pin retention

Ordering designation	Package contents	Sales pack quantity	Item number
SIW 22T-A 1/2" cas	1x Cordl. impact wrench SIW 22T-A assy, 1x Impact socket S-NSD 1/2"-13 S, 1x Impact socket S-NSD 1/2"-15 S, 1x Impact socket S-NSD 1/2"-13 L, 1x Impact socket S-NSD 1/2"-15 L, 1x Case	1 pc	409459



Cordless compact drill driver SFC 14-A



CPC

Key applications and advantages

- Driving screws up to 6 mm diameter in wood
- Driving screws for plastic anchors up to 8 mm diameter
- Driving self-tapping screws up to 4.8 mm diameter in metal
- Very compact design for best-possible access in tight corners
- Compact and durable Hilti Lithium CPC battery for high performance and long life

Technical data

Rated voltage	14.4 V
Reversing switch	Yes
Battery capacity	1.6 Ah
Battery type	Li-ion
Bit diameter range steel twist - max.	10 mm
Rotation speed gear 1 under no load	500 rpm
Rotation speed gear 2 under no load	1700 rpm
Max. torque (soft joint)	24 Nm
Max. torque hard joint	45 Nm
Torque increments	15

Ordering designation	Package contents	Sales pack quantity	Item number
SFC 14-A cas	1x Cordl. compact drill driver SFC 14-A CE, 1x Case	1 pc	429275

Cordless impact wrench SIW 14-A



Key applications and advantages

- Driving 6 mm HUS3 screw anchors in concrete
- Driving 8 mm and 10 mm HRD frame anchors in masonry and concrete
- Driving lag bolts up to 8 mm in diameter in wood
- Brushless motor for long lifetime and more work per charge
- Compact design allows easy use in tight corners and wherever space is limited







Technical data

Rated voltage	14.4 V
Reversing switch	Yes
Battery capacity	3.3 Ah
Battery type	B 14/3.3 Li-ion
Max. torque, setting 1	80 Nm
Rotation speed gear 1 under no load	1000 rpm
Max. torque, setting 2	120 Nm
Max. torque, setting 3	185 Nm
Rotation speed gear 3 under no load	2300 rpm
Full hammering frequency	3400 impacts/minute

Ordering designation	Package contents	Sales pack quantity	Item number
SIW 14-A 1/2" cas	1x Cordl. impact wrench SIW 14-A 1/2", 1x Case	1 pc	2006066

Accessories for Cordless Drills and Impact Drivers, Wrenches

Cordless Systems

Ordering designation		SIW 22-A	SFH 22-A	SIW 22T-A 1/2"	Sales pack quantity	Item number
Battery charger C 4/36-350 110V box		■	■	■	1 pc	2028992
Battery charger C 4/36-350 230V box		■	■	■	1 pc	2028876
Battery charger C 4/36-90 110V box			■		1 pc	2015763
Battery charger C 4/36-90 230V box			■		1 pc	2015762
Battery charger C 4/36-90 230V box			■		1 pc	2015761
Battery pack B 22/3.3 Li-Ion		■	■	■	1 pc	2007431

HSS bit sets (metric) HSS sets



Key applications and advantages

- Drilling in unalloyed and medium alloyed steel
- High-speed steel drill bit with split point, 135° tip angle

Technical data

Base material	Steel, Aluminium, Carbon steel, Metal, Medium alloyed steel, Unalloyed steel
Material composition	HSS M2 steel
Working mode	Drilling only

Ordering designation	Sales pack quantity	Item number
HSS 2-8 set	1 pc	213950
HSS 1-10 kit	1 pc	304938
HSS 1-13 kit	1 pc	304939
HSS 1-10 set	1 pc	405312

Bits metric HSS



Key applications and advantages

- Drilling in unalloyed and medium-alloyed steel
- High-speed steel drill bit with split point, 135° tip angle
- Ideal for use with Hilti cordless tools

Technical data

Base material	Metal, Steel, Medium alloyed steel, Unalloyed steel, Aluminium
Material coating/plating/finish	HSS M2 steel
Working mode	Drilling only

Ordering designation	Diameter	Length	Working length	Sales pack quantity	Item number
HSS 1,0x34mm "MP10	1 mm	34 mm	12 mm	10 pc	304898
HSS 1,5x40mm "MP10	1.5 mm	40 mm	18 mm	10 pc	304899
HSS 2,5x43mm "MP10	2.5 mm	43 mm	20 mm	10 pc	304901
HSS 2,0x49mm "MP10	2 mm	49 mm	24 mm	10 pc	304900
HSS 2,5x57mm "MP10	2.5 mm	57 mm	30 mm	10 pc	304902
HSS 3,3x49mm "MP10	3.3 mm	49 mm	24 mm	10 pc	304906
HSS 3,0x61mm "MP10	3 mm	61 mm	33 mm	10 pc	304903
HSS 3,2x65mm "MP10	3.2 mm	65 mm	36 mm	10 pc	304904
HSS 3,5x70mm "MP10	3.5 mm	70 mm	39 mm	10 pc	304908
HSS 3,75x70mm "MP10	3.75 mm	70 mm	39 mm	10 pc	304909
HSS 4,0x75mm "MP10	4 mm	75 mm	43 mm	10 pc	304910
HSS 4,2x75mm "MP10	4.2 mm	75 mm	43 mm	10 pc	304912
HSS 4,25x75mm "MP10	4.25 mm	75 mm	43 mm	10 pc	304913
HSS 4,5x80mm "MP10	4.5 mm	80 mm	47 mm	10 pc	304914
HSS 4,75x86mm "MP10	4.75 mm	86 mm	52 mm	10 pc	304915
HSS 5,0x86mm "MP10	5 mm	86 mm	52 mm	10 pc	304916
HSS 5,2x86mm "MP10	5.2 mm	86 mm	52 mm	10 pc	304917
HSS 5,25x86mm "MP10	5.25 mm	86 mm	52 mm	10 pc	304918
HSS 5,5x93mm "MP10	5.5 mm	93 mm	57 mm	10 pc	304920
HSS 5,7x93mm "MP10	5.7 mm	93 mm	57 mm	10 pc	304921
HSS 5,75x93mm "MP10	5.75 mm	93 mm	57 mm	10 pc	304922
HSS 5,5x139mm "MP10	5.5 mm	139 mm	91 mm	10 pc	383780
HSS 6,0x93mm "MP10	6 mm	93 mm	57 mm	10 pc	304923
HSS 6,5x101mm "MP10	6.5 mm	101 mm	63 mm	10 pc	304924
HSS 7,0x109mm "MP10	7 mm	109 mm	69 mm	10 pc	304925
HSS 7,5x109mm "MP10	7.5 mm	109 mm	69 mm	10 pc	304926
HSS 8,0x117mm "MP10	8 mm	117 mm	75 mm	10 pc	304927
HSS 8,5x117mm "MP10	8.5 mm	117 mm	75 mm	10 pc	304928
HSS 9,0x125mm "MP10	9 mm	125 mm	81 mm	10 pc	304929
HSS 9,5x125mm "MP10	9.5 mm	125 mm	81 mm	10 pc	304930
HSS 10,50x133mm "MP5	10.5 mm	133 mm	87 mm	5 pc	304932
HSS 10,0x133mm "MP10	10 mm	133 mm	87 mm	10 pc	304931
HSS 11,0x142mm "MP5	11 mm	142 mm	94 mm	5 pc	304933
HSS 11,5x142mm "MP5	11.5 mm	142 mm	94 mm	5 pc	304934
HSS 12,0x151mm "MP5	12 mm	151 mm	101 mm	5 pc	304935
HSS 12,5x151mm "MP5	12.5 mm	151 mm	101 mm	5 pc	304936
HSS 13,0x151mm "MP5	13 mm	151 mm	101 mm	5 pc	304937
HSS 14,0x160mm	14 mm	160 mm	108 mm	1 pc	2066674
HSS 15,0x169mm	15 mm	169 mm	114 mm	1 pc	2066675

Ordering designation	Diameter	Length	Working length	Sales pack quantity	Item number
HSS 16,0x178mm	16 mm	178 mm	178 mm	1 pc	2066676
HSS 17,0x184mm	17 mm	184 mm	125 mm	1 pc	2066677
HSS 18,0x191mm	18 mm	191 mm	130 mm	1 pc	2066678

HSS cobalt bits (metric) HSS Co



Key applications and advantages

- Drilling in stainless steel, high-tensile steel, high-temperature alloys, heat-treated materials
- Split point for precise drilling

Technical data

Base material	Alloyed steel, stainless steel, hardened grades of stainless steel
Material composition	HSS M35 steel
Working mode	Drilling only

Ordering designation	Diameter	Working length	Sales pack quantity	Item number
HSS Co 1,0x34mm MP10	1 mm	12 mm	10 pc	2071111
HSS Co 1,5x40mm MP10	1.5 mm	18 mm	10 pc	2071112
HSS Co 2,5x43mm MP10	2.5 mm	14 mm	10 pc	2071115
HSS Co 2,0x49mm MP10	2 mm	24 mm	10 pc	2071113
HSS Co 2,1x49mm MP10	2.1 mm	24 mm	10 pc	2071114
HSS Co 2,5x57mm MP10	2.5 mm	30 mm	10 pc	2071116
HSS Co 3,3x49mm MP10	3.3 mm	18 mm	10 pc	2071130
HSS Co 3,0x61mm MP10	3 mm	33 mm	10 pc	2071117
HSS Co 3,2x65mm MP10	3.2 mm	36 mm	10 pc	2071118
HSS Co 3,25x65mm MP10	3.25 mm	36 mm	10 pc	2071119
HSS Co 3,3x65mm MP10	3.3 mm	36 mm	10 pc	2071131
HSS Co 3,5x70mm MP10	3.5 mm	39 mm	10 pc	2071132
HSS Co 3,75x70mm MP10	3.75 mm	39 mm	10 pc	2071133
HSS Co 4,0x75mm MP10	4 mm	43 mm	10 pc	2071134
HSS Co 4,1x75mm MP10	4.1 mm	43 mm	10 pc	2071135
HSS Co 4,2x75mm MP10	4.2 mm	43 mm	10 pc	2071136
HSS Co 4,25x75mm MP10	4.25 mm	43 mm	10 pc	2071137
HSS Co 4,5x80mm MP10	4.5 mm	47 mm	10 pc	2071138
HSS Co 4,75x80mm MP10	4.75 mm	47 mm	10 pc	2071139
HSS Co 4,8x86mm MP10	4.8 mm	52 mm	10 pc	2071140
HSS Co 4,9x86mm MP10	4.9 mm	52 mm	10 pc	2071141
HSS Co 5,0x86mm MP10	5 mm	52 mm	10 pc	2071142
HSS Co 5,1x86mm MP10	5.1 mm	52 mm	10 pc	2071143
HSS Co 5,2x86mm MP10	5.2 mm	52 mm	10 pc	2071144
HSS Co 5,25x86mm MP10	5.25 mm	52 mm	10 pc	2071145
HSS Co 5,3x86mm MP10	5.3 mm	52 mm	10 pc	2071146
HSS Co 5,4x93mm MP10	5.4 mm	57 mm	10 pc	2071147
HSS Co 5,5x93mm MP10	5.5 mm	57 mm	10 pc	2071148
HSS Co 5,6x93mm MP10	5.6 mm	57 mm	10 pc	2071149
HSS Co 5,7x93mm MP10	5.7 mm	57 mm	10 pc	2071150
HSS Co 5,75x93mm MP10	5.75 mm	57 mm	10 pc	2071151
HSS Co 5,8x93mm MP10	5.8 mm	57 mm	10 pc	2071152
HSS Co 5,9x93mm MP10	5.9 mm	57 mm	10 pc	2071153
HSS Co 6,0x93mm MP10	6 mm	57 mm	10 pc	2071154
HSS Co 6,5x101mm MP10	6.5 mm	63 mm	10 pc	2071155
HSS Co 6,7x101mm MP10	6.7 mm	63 mm	10 pc	2071156
HSS Co 6,8x109mm MP10	6.8 mm	69 mm	10 pc	2071157
HSS Co 7,0x109mm MP10	7 mm	69 mm	10 pc	2071160
HSS Co 7,5x109mm MP10	7.5 mm	69 mm	10 pc	2071161
HSS Co 8,0x117mm MP10	8 mm	75 mm	10 pc	2071162
HSS Co 8,5x117mm MP10	8.5 mm	75 mm	10 pc	2071163
HSS Co 9,0x125mm MP10	9 mm	81 mm	10 pc	2071164
HSS Co 9,5x125mm MP10	9.5 mm	81 mm	10 pc	2071165
HSS Co 9,8x133mm MP10	9.8 mm	87 mm	10 pc	2071166
HSS Co 10,5x133mm MP5	10.5 mm	87 mm	5 pc	2071169
HSS Co 10,0x133mm MP10	10 mm	87 mm	10 pc	2071167
HSS Co 11,0x142mm MP5	11 mm	94 mm	5 pc	2071170
HSS Co 11,5x142mm MP5	11.5 mm	94 mm	5 pc	2071171
HSS Co 12,0x151mm MP5	12 mm	101 mm	5 pc	2071172
HSS Co 12,5x151mm MP5	12.5 mm	101 mm	5 pc	2071173
HSS Co 13,0x151mm	13 mm	101 mm	1 pc	2071174
HSS Co 14,0x160mm	14 mm	108 mm	1 pc	2071175
HSS Co 15,0x169mm	15 mm	114 mm	1 pc	2071176
HSS Co 16,0x178mm	16 mm	120 mm	1 pc	2071177

Ordering designation	Diameter	Working length	Sales pack quantity	Item number
HSS Co 17.0x184mm	17 mm	125 mm	1 pc	2071178
HSS Co 18.0x191mm	18 mm	130 mm	1 pc	2071179

MultiCut bimetal hole saw HS-MU



Key applications and advantages

- Cutting holes in drywall, wood, aluminum and PVC sheets
- HSS cobalt (8%) alloy for longer lifetime and higher performance
- Special tooth design for fast cutting and good chip clearance

Technical data

Working length	40 mm
Base material	Drywall, Plastic, Wood, Metal
Working mode	Drilling only

Ordering designation	Diameter	Sales pack quantity	Item number
14mm-9/16" MultiCut	14 mm	1 pc	417595
16mm-5/8" MultiCut	16 mm	1 pc	417596
17mm-11/16" MultiCut	17 mm	1 pc	417597
19mm-3/4" MultiCut	19 mm	1 pc	417598
20mm-25/32" MultiCut	20 mm	1 pc	417599
21mm-13/16" MultiCut	21 mm	1 pc	417600
22mm-7/8" MultiCut	22 mm	1 pc	417601
24mm-15/16" MultiCut	24 mm	1 pc	417602
25mm-1" MultiCut	25 mm	1 pc	417603
27mm-1 1/16" MultiCut	27 mm	1 pc	417604
29mm-1 1/8" MultiCut	29 mm	1 pc	417605
30mm-1 3/16" MultiCut	30 mm	1 pc	417606
32mm-1 1/4" MultiCut	32 mm	1 pc	417607
33mm-1 5/16" MultiCut	33 mm	1 pc	417608
35mm-1 3/8" MultiCut	35 mm	1 pc	417609
37mm-1 7/16" MultiCut	37 mm	1 pc	417610
38mm-1 1/2" MultiCut	38 mm	1 pc	417611
40mm-1 9/16" MultiCut	40 mm	1 pc	417612
41mm-1 5/8" MultiCut	41 mm	1 pc	417613
43mm-1 11/16" MultiCut	43 mm	1 pc	417614
44mm-1 3/4" MultiCut	44 mm	1 pc	417615
46mm-1 13/16" MultiCut	46 mm	1 pc	417616
48mm-1 7/8" MultiCut	48 mm	1 pc	417617
51mm-2" MultiCut	51 mm	1 pc	417618
52mm-2 1/16" MultiCut	52 mm	1 pc	417619
54mm-2 1/8" MultiCut	54 mm	1 pc	417620
56mm-2 3/16" MultiCut	56 mm	1 pc	417621
57mm-2 1/4" MultiCut	57 mm	1 pc	417622
59mm-2 5/16" MultiCut	59 mm	1 pc	417623
60mm-2 3/8" MultiCut	60 mm	1 pc	417624
64mm-2 1/2" MultiCut	64 mm	1 pc	417625
65mm-2 9/16" MultiCut	65 mm	1 pc	417626
67mm-2 5/8" MultiCut	67 mm	1 pc	417627
68mm-2 11/16" MultiCut	68 mm	1 pc	417628
70mm-2 3/4" MultiCut	70 mm	1 pc	417629
73mm-2 7/8" MultiCut	73 mm	1 pc	417630
76mm-3" MultiCut	76 mm	1 pc	417631
79mm-3 1/8" MultiCut	79 mm	1 pc	417632
83mm-3 1/4" MultiCut	83 mm	1 pc	417633
86mm-3 3/8" MultiCut	86 mm	1 pc	417634
89mm-3 1/2" MultiCut	89 mm	1 pc	417635
92mm-3 5/8" MultiCut	92 mm	1 pc	417636
95mm-3 3/4" MultiCut	95 mm	1 pc	417637
98mm-3 7/8" MultiCut	98 mm	1 pc	417638
102mm-4" MultiCut	102 mm	1 pc	417639
105mm-4 1/8" MultiCut	105 mm	1 pc	417640
108mm-4 1/4" MultiCut	108 mm	1 pc	417641
111mm-4 3/8" MultiCut	111 mm	1 pc	417642
114mm-4 1/2" MultiCut	114 mm	1 pc	417643
121mm-4 3/4" MultiCut	121 mm	1 pc	417644

Ordering designation	Diameter	Sales pack quantity	Item number
127mm-5" MultiCut	127 mm	1 pc	417645
140mm-5 1/2" MultiCut	140 mm	1 pc	417646
152mm-6" MultiCut	152 mm	1 pc	417647

MultiCut bimetal hole saw adaptor and accessories HS-MU



Key applications and advantages

- Quick-change system for hole saws and centering bit
- HSS split-point centring bit with 135° point angle and 1/4" hex shank
- Convenient quick release of the centering bit from the hole saw

Technical data

Base material	Drywall, Wood, Plastic, Metal
Connection end	Hexagonal
Material composition	HSS M2 steel
Working mode	Drilling only

Ordering designation	Diameter	Sales pack quantity	Item number
Hole saw arbor		1 pc	283871
6 mm	6 mm	5 pc	283870



MetalCut bimetal hole saw HS-ME



Key applications and advantages

- Cutting holes in stainless steel, steel and metal sheets
- Safety stopper to prevent breaking through
- HSS cobalt (8%) alloy for longer lifetime and higher performance

Technical data

Working length	28 mm
Base material	Steel, Non-ferrous metal
Working mode	Drilling only

Ordering designation	Diameter	Sales pack quantity	Item number
16mm-5/8" MetalCut	16 mm	1 pc	417550
17mm-11/16" MetalCut	17 mm	1 pc	417552
19mm-3/4" MetalCut	19 mm	1 pc	417553
20mm-25/32" MetalCut	20 mm	1 pc	417555
21mm-13/16 MetalCut	21 mm	1 pc	417557
22mm-7/8 MetalCut	22 mm	1 pc	417558
25mm-1" MetalCut	25 mm	1 pc	417560
27mm-1 1/16" MetalCut	27 mm	1 pc	417562
29mm-1 1/8" MetalCut	29 mm	1 pc	417563
30mm-1 3/16" MetalCut	30 mm	1 pc	417565
32mm-1 1/4" MetalCut	32 mm	1 pc	417567
33mm-1 5/16" MetalCut	33 mm	1 pc	417568
35mm-1 3/8" MetalCut	35 mm	1 pc	417569
38mm-1 1/2" MetalCut	38 mm	1 pc	417570
40mm-1 9/16" MetalCut	40 mm	1 pc	417572
41mm-1 5/8" MetalCut	41 mm	1 pc	417573
44mm-1 3/4" MetalCut	44 mm	1 pc	417574
48mm-1 7/8" MetalCut	48 mm	1 pc	417576
51mm-2" MetalCut	51 mm	1 pc	417577
54mm-2 1/8" MetalCut	54 mm	1 pc	417578
57mm-2 1/4" MetalCut	57 mm	1 pc	417579
60mm-2 3/8 MetalCut	60 mm	1 pc	417580
64mm-2 1/2" MetalCut	64 mm	1 pc	417581
65mm-2 9/16" MetalCut	65 mm	1 pc	417582

Ordering designation	Diameter	Sales pack quantity	Item number
67mm-2 5/8" MetalCut	67 mm	1 pc	417583
68mm-2 11/16" MetalCut	68 mm	1 pc	417584

MetalCut bimetal adaptor and accessories HS-ME



Key applications and advantages

- Quick-change system for hole saws and centring bit
- Quick and reliable hole saw attachment and release
- HSS cobalt split-point centering bit with 135° point angle and 1/4" hex shank

Technical data

Base material	Steel and stainless steel, Aluminium
Connection end	Hexagonal
Material composition	HSS M35 steel
Working mode	Drilling only

Ordering designation	Sales pack quantity	Item number
Hole saw arbor MetalCut	1 pc	216214
HSS-Co	5 pc	206040

Stepper bit HSS SB



Key applications and advantages

- Drilling through thin sheet metal in electrical and building applications
- High-speed steel drill bit with split point for accurate drilling
- Diameter markings on inner edge for greater convenience

Technical data

Base material	Metal
Material composition	HSS M2 steel
Working mode	Drilling only

Ordering designation	Length	Working length	Sales pack quantity	Item number
4-20	73 mm	48 mm	1 pc	304983
M10-M40	97 mm	72 mm	1 pc	304984

Spade bit WDB S



Key applications and advantages

- Drilling small- to medium-diameter holes in soft or hard wood
- Ideal for drilling overhead, for use with SID impact tools
- Self-feeding threaded tip allows drilling with less effort and reduces vibration
- Connection end with hex shank groove for use with all SID, SFH and SF power tools

Technical data

Working length	100 mm
Base material	Wood
Connection end	1/4 in hexagonal
Working mode	Drilling only

Ordering designation	Diameter	Sales pack quantity	Item number
WDB-S-H6 6x152	6 mm	1 pc	2025565
WDB-S-H6 8x152	8 mm	1 pc	2025566
WDB-S-H6 10x152	10 mm	1 pc	2025567
WDB-S-H6 12x152	12 mm	1 pc	2025568
WDB-S-H6 14x152	14 mm	1 pc	2025569
WDB-S-H6 16x152	16 mm	1 pc	2025570
WDB-S-H6 18x152	18 mm	1 pc	2025571
WDB-S-H6 20x152	20 mm	1 pc	2025572
WDB-S-H6 22x152	22 mm	1 pc	2025573
WDB-S-H6 24x152	24 mm	1 pc	2025574
WDB-S-H6 25x152	25 mm	1 pc	2025575
WDB-S-H6 26x152	26 mm	1 pc	2025576
WDB-S-H6 28x152	28 mm	1 pc	2025577
WDB-S-H6 30x152	30 mm	1 pc	2025578
WDB-S-H6 32x152	32 mm	1 pc	2025579
WDB-S-H6 35x152	35 mm	1 pc	2025580
WDB-S-H6 38x152	38 mm	1 pc	2025581

Spade bit accessories WDB S



Key applications and advantages

- Extends the length of spade bits

Technical data

Base material	Wood
Connection end	1/4 in hexagonal
Working mode	Drilling only

Ordering designation	Length	Sales pack quantity	Item number
WDB-S-H1/4 E6	152 mm	1 pc	2033438
WDB-S-H1/4 E12	304 mm	1 pc	2025583

Auger bit WDB A



Key applications and advantages

- Accurate drilling in wood, heavy timber and nail-embedded wood, also suitable for deep drilling
- Self-feeding threaded tip helps pull the bit through the wood
- Large flutes for efficient chip removal

Technical data

Base material	Wood
Connection end	Hexagonal
Working mode	Drilling only

Ordering designation	Diameter	Length	Working length	Sales pack quantity	Item number
8x255/320	8 mm	320 mm	255 mm	1 pc	304988
10x255/320	10 mm	320 mm	255 mm	1 pc	304989
10x400/460	10 mm	460 mm	400 mm	1 pc	304990
12x255/320	12 mm	320 mm	255 mm	1 pc	304991
12x400/460	12 mm	460 mm	400 mm	1 pc	304992
14x255/320	14 mm	320 mm	255 mm	1 pc	304993
14x400/460	14 mm	460 mm	400 mm	1 pc	304994
16x255/320	16 mm	320 mm	255 mm	1 pc	304995
16x400/460	16 mm	460 mm	400 mm	1 pc	304996
18x255/320	18 mm	320 mm	255 mm	1 pc	304997
18x400/460	18 mm	460 mm	400 mm	1 pc	304998
20x255/320	20 mm	320 mm	255 mm	1 pc	304999
20x400/460	20 mm	460 mm	400 mm	1 pc	305000
22x255/320	22 mm	320 mm	255 mm	1 pc	305001
22x400/460	22 mm	460 mm	400 mm	1 pc	305002
24x400/460	24 mm	460 mm	400 mm	1 pc	305003
26x160/235	26 mm	235 mm	160 mm	1 pc	305004
26x255/320	26 mm	320 mm	255 mm	1 pc	305005
28x255/320	28 mm	320 mm	255 mm	1 pc	305007
30x255/320	30 mm	320 mm	255 mm	1 pc	305009
32x255/320	32 mm	320 mm	255 mm	1 pc	305011

Torsion bit sets S-BS (T)



Key applications and advantages

- 1/4" hexagon, torsion zone for long service life
- Torsion zone cushions higher impacts
- Extra-high strength reduces the risk of premature bit breakage

Technical data

Connection end	1/4 in hexagonal
Feature	Torsion bits

Ordering designation	Length - L	Sales pack quantity	Item number
S-BSC+ UNI 25/1" T (10)	25 mm	1 pc	2039186

System screwdriver bits S-SY B



Key applications and advantages

- 1/4" hexagon
- Screwdriver bits specially for use with Hilti tools
- Perfectly matched to Hilti tools and consumables
- Superior service life as part of the complete Hilti system

Technical data

Feature	Torsion bits, Impact bits
---------	---------------------------

Ordering designation	Length - L	Sales pack quantity	Item number
S-SY TX45 35 HUS (5)	35 mm	5 pc	2094673
S-SY TX50 35 HUS (5)	35 mm	5 pc	2094675
S-SY PH2 116/4 1/2" (10)	116 mm	10 pc	2039152

Torsion screwdriver bits S-B (T)



Key applications and advantages

- 1/4" hexagon, torsion zone for long service life
- Torsion zone cushions higher impacts
- Particularly high strength reduces the risk of premature bit breakage

Technical data

Connection end	1/4 in hexagonal
Feature	Torsion bits

Ordering designation	Length - L	Sales pack quantity	Item number
S-B PH2 25/1" T (10)	25 mm	10 pc	2038979
S-B TX25 25/1" T (10)	25 mm	10 pc	2039059
S-B TX30 25/1" T (10)	25 mm	10 pc	2039062
S-B PH1 25/1" T (25)	25 mm	25 pc	2038976
S-B PZ1 25/1" T (25)	25 mm	25 pc	2039045

Magnetic bit holder S-BH (M)



Key applications and advantages

- Fits all 1/4" screwdriver bits made according to DIN 3126 C 6.3 and E 6.3
- With stainless steel sleeve and strong permanent magnet

Technical data

Connection end	1/4 in hexagonal
Feature	Magnetic nutsetters

Ordering designation	Length - L	Sales pack quantity	Item number
S-BH M 50/2"	50 mm	1 pc	2038758
S-BH M 75/3"	75 mm	1 pc	2038759

Quick-change bit holder S-BH (QC)



Key applications and advantages

- Fits all 1/4" screwdriver bits in accordance with DIN 3126 C 6.3 and E 6.3
- Bits can be changed with one hand
- No extra tools needed to remove bits

Technical data

Connection end	1/4 in hexagonal
Feature	Torsion bits

Ordering designation	Length - L	Sales pack quantity	Item number
S-BH QC 50/2"	50 mm	1 pc	2039217

Socket S-NS (C)



Key applications and advantages

- Socket for use with hexagonal head screws
- Non-magnetic design with ring and bearing to hold screw
- One socket suitable for use with stainless and carbon steel screws

Technical data

Connection end	1/4 in hexagonal
Feature	Mechanical nutsetters

Ordering designation	Length - L	Sales pack quantity	Item number
S-NS 7 C 50/2"	50 mm	1 pc	2039243
S-NS 8 C 50/2"	50 mm	1 pc	2039244
S-NS 10 C 50/2"	50 mm	1 pc	2039245
S-NS 1/4" C 50/2"	50 mm	1 pc	2039248
S-NS 3/8" C 50/2"	50 mm	1 pc	2039250



Cordless combihammer TE 30-A36



Key applications and advantages

- Drilling anchor holes and through-holes in concrete and masonry, diameter range 4 - 28 mm, recommended range 10 - 20 mm
- Drilling for non-structural rebar doweling, diameter range 4 - 28 mm, recommended range 8 - 20 mm
- Corrective chiselling
- Cordless combihammer for higher productivity through greater mobility
- Features a brushless motor for the highest performance in its class and superior system efficiency

Technical data

Voltage	36 V
Rated voltage	36 V
Battery capacity	6 Ah
Battery type	Li-ion
Battery energy	216 Wh
Number of gears	1
Optimum drilling diameter range for hammer drill bits	10 - 20 mm
Drilling diameter range for hammer drill bits	4 - 28 mm
Working mode	Hammer drilling, Chiselling
Single impact energy	3.6 J



Ordering designation	Package contents	Sales pack quantity	Item number
TE 30-A36 cas	1x Cordless combihammer TE 30-A36, 1x Case	1 pc	2029312



Cordless reciprocating saw WSR 22-A



Key applications and advantages

- Cutting metal pipes and conduits
- Cutting reinforcing bars, threaded rods and metal profiles
- Cutting window frames, woodwork and plastics
- Makes about twice as many cuts in metal per battery charge as other reciprocating saws of the same class
- Unique Active Vibration Reduction (AVR): the low-vibration vertical gearing system and spring-cushioned contact shoe greatly reduce vibration and thus enable smooth, easy cutting

Technical data

A-weighted emission sound pressure level¹⁾	82 dB (A)
Variable speed switch	Yes
Weight according to EPTA Procedure 01/2003	3.8 kg
Active Vibration Reduction	Yes
Approvals	CE
Base material	Metal, Wood and plastics
Battery capacity	3.3 Ah
Battery energy	71.28 Wh
Battery type	Li-ion
Blade clamp	1/2" keyless

¹⁾ according to EN 60745



AVR CPC

Ordering designation	Package contents	Sales pack quantity	Item number
WSR 22-A cas	1x Cordless reciprocating saw WSR 22-A assy, 1x Case	1 pc	404151

Cordless reciprocating saw WSR 36-A



Key applications and advantages

- Fast cutting in wood
- Cutting pipes overhead or in difficult-to-reach places
- Cutting wood and metal in demolition work
- Revolutionary D-grip and ergonomically positioned controls for superior handling in all working positions
- Low weight and compact design for maximum mobility even in tight spaces

Technical data

A-weighted emission sound pressure level¹⁾	90 dB (A)
Variable speed switch	Yes
Weight according to EPTA Procedure 01/2003	4.4 kg
Active Vibration Reduction	Yes
Approvals	CE
Base material	Metal, Wood, Mineral
Battery capacity	3.0 Ah
Battery energy	108 Wh
Battery type	Li-ion
Blade clamp	1/2" keyless

¹⁾ according to EN 60745

Ordering designation	Package contents	Sales pack quantity	Item number
WSR 36-A cas	1x Cordless reciprocating saw WSR 36-A, 1x Case	1 pc	213997



Cordless circular saw for cutting metal SCM 22-A



Key applications and advantages

- Cutting channels and pipes on the job-site quickly, with the highest possible accuracy
- Cutting openings in sheet metal in heating and air conditioning installation work
- Cutting sandwich panels, mesh and corrugated sheet metal
- More than 100 cuts in MQ41 channel possible with one battery charge
- Weight of less than 4 kg for best handling and ease of use

Technical data

A-weighted emission sound pressure level¹⁾	77 dB (A)
Max. cutting depth	57 mm
Variable speed switch	Yes
Weight according to EPTA Procedure 01/2003	4 kg
Approvals	CE
Arbour	20 mm
Base material	Metal and metal sandwich
Base plate - length	248 mm
Base plate - width	127 mm
Base plate dimensions (LxW)	248 x 127 mm

¹⁾ according to EN 60745



Ordering designation	Package contents	Sales pack quantity	Item number
SCM 22-A cas	1x Cordless circular saw SCM 22-A, 1x Circ. saw blade SC-C MU 165x20 z40 A(20), 1x Case	1 pc	2024449

Cordless circular saw SCW 22-A



Key applications and advantages

- General construction: cutting formwork boards, OSB, plywood, chipboard, plastics, rafters and battens
- Interior finishing: cutting drywall board, cement board, MDF and HDF
- Cutting formwork boards, planks, battens, OSB, chipboard, plywood sheets and plastics
- Impressive cutting performance for a tool of this size and weight
- Compatible with all Hilti 22V batteries, accurate battery charge status display

Technical data

A-weighted emission sound pressure level¹⁾	93 dB (A)
Max. cutting depth	57 mm
Variable speed switch	Yes
Weight according to EPTA Procedure 01/2003	3.9 kg
Approvals	CE
Arbour	20 mm
Base material	Wood and wood sandwich
Base plate - length	298 mm
Base plate - width	137 mm
Base plate dimensions (LxW)	298 x 137 mm

¹⁾ according to EN 60745



Ordering designation	Package contents	Sales pack quantity	Item number
SCW 22-A cas	1x Cordless circular saw SCW 22-A, 1x Rail adapter SCW assy, 1x Case	1 pc	423165



Cordless angle grinder AG 125-A22



Key applications and advantages

- Finishing
- Demolition
- Cutting and grinding steel and other metals
- Best ergonomic design and safety features of all comparable tools on the market (disc brake, ATC, automatic off)
- 30-40 % higher performance and battery capacity than competitors' tools

Technical data

Base material	Metal, Mineral, Stainless steel
Disc diameter	125 mm
A-weighted emission sound power level¹⁾	94 dB (A)
No-load speed	9500 rpm
Weight according to EPTA Procedure 01/2003	2.7 kg

¹⁾ according to EN 60745



Ordering designation	Package contents	Sales pack quantity	Item number
AG 125-A22 cas	1x Cordless angle grinder AG 125-A22, 1x Clip-on front cover 125, 1x Case	1 pc	2004075
AG 125-A22 cas	1x Cordless angle grinder AG 125-A22, 1x Clip-on front cover 125, 1x Case	1 pc	2026375



Technical data	
Dispenser, setting tool, accessory, tester type	Dispensers
Battery type	22 V
Dispenser type	Battery
Power source type	Compact B22/1.6 or B22/3.3 battery

Key applications and advantages

- Injection of Hilti HIT adhesive mortar for fastening anchor rods and rebars in concrete and masonry
- No need for an external power source
- Serial fastenings and/or injection in deep drilled holes
- Easy injection even at low temperatures
- Dose adjustment knob for accurate, controlled dispensing



Cordless electric dispenser HDE 500-A22



Ordering designation	Weight	Sales pack quantity	Item number
HDE 500-A22 box	2.2 kg	1 pc	2005630
HDE 500-A22 CR/CB cas	2.2 kg	1 pc	2005637

Overview Battery packs



	B 12/2.6 Li-Ion	B 14/1.6 Li-Ion	B 14/3.3 Li-Ion	B 22/1.6 Li-Ion	B 22/3.3 Li-Ion	B 36/3.0 Li-Ion	B 36/6.0 Li-Ion
Item number	2077976	426174	426175	426177	2007431	418009	2018896
Technical Features							
Battery capacity	2.6 Ah	1.6 Ah	3.3 Ah	1.6 Ah	3.3 Ah	3.0 Ah	6.0 Ah
Battery type	Li-Ion	Li-Ion	Li-Ion	Li-Ion	Li-Ion	Li-Ion	Li-Ion
Voltage	12V	14.4 V	14.4 V	21.6 V	21.6 V	36 V	36 V
Cordless Power Care	Yes	Yes	Yes	Yes	Yes	Yes	Yes
Make it fit	Yes	Yes	Yes	Yes	Yes	Yes	Yes
Dimensions (mm)	96 x 75 x 45	103 x 81 x 51	103 x 81 x 69	135 x 94 x 53	150 x 95 x 81	155 x 95 x 80	180 x 97 x 98
Weight according to EPTA Procedure 01/2003	0.2 kg	0.4 kg	0.6 kg	0.5 kg	0.8 kg	1.2 kg	1.8 kg
Related Cordless tools							
TE 2-A22				■	■		
TE 4-A22					■		
TE 6-A36-AVR						■	
SD 2-A	■						
SFD 2-A	■						
SFC 14-A		■	■				
SFC 22-A				■	■		
SFH 22-A				■	■		
SIW 14-A		■	■				
SIW 22-A					■		
SIW 22-A 1/2"					■		
TE 30-A36							■
WSR 22-A					■		
WSR 36-A						■	
SCM 22-A					■		
SCW 22-A					■		
AG 125-A22					■		
HDE 500-A22				■	■		














Overview Battery chargers



Cordless Systems

	C4/12-50	C 4/36-90			C 4/36-350		
Item number	2077004	2015762	2015763	2015761	2028876	2028992	2028875
Technical Features							
Voltage	230V	230V	110V	110V	230V	110V	230V
Output power	50 W	90W	90W	90W	350 W	350 W	350 W
Plug type	GB	GB	GB	EU	GB	GB	EU
Cordless Power Care	Yes	Yes	Yes	Yes	Yes	Yes	Yes
Make it Fit	-	Yes	Yes	Yes	Yes	Yes	Yes
Dimensions (mm)	137 x 90 x 60	169 x 122 x 70	169 x 122 x 70	169 x 122 x 70	170 x 163 x 70	170 x 163 x 70	170 x 163 x 70
Weight according to EPTA Procedure 01/2003	0.4 kg	0.6 kg	0.6 kg	0.6 kg	1.1 kg	1.1 kg	1.1 kg
Related Cordless tools							
TE 2-A22		■	■	■			
TE 4-A22		■	■	■			
TE 6-A36-AVR					■	■	■
SD 2-A	■						
SFD 2-A	■						
SFC 14-A		■	■	■			
SFC 22-A		■	■	■			
SFH 22-A		■	■	■			
SIW 14-A		■	■	■			
SIW 22-A		■	■	■			
SIW 22-A 1/2"		■	■	■			
TE 30-A36					■	■	■
WSR 22-A		■	■	■			
WSR 36-A					■	■	■
SCM 22-A		■	■	■			
SCW 22-A		■	■	■			
WSC 70-A36					■	■	■
AG 125-A22		■	■	■			
HDE 500-A22		■	■	■			

Overview Cordless tools accessories

	Order description	Tools	Item number
	Screw driver bit S-B PH2 25/1" T (10)	SFC 14-A, SFH 22-A	2038979
	Bit set S-BSC+ UNI 25/1" T (10)	SFC 14-A, SFH 22-A	2039186
	Socket wrench insert S-NSD 8	SFC 14-A, SFH 22-A	308901
	Socket wrench insert S-NSD 10	SFC 14-A, SFH 22-A	308902
	Socket wrench insert S-NSD 3/8"	SFC 14-A, SFH 22-A	308905
	Chuck TE 2-M NG/TE 7-C assy	TE 6-A36	273118
	Quick-release chuck TE 2M/7C/7A/6A Li	TE 6-A36	224119
	Angular chuck TE-AC 1	TE 6-A36	272701
	Bit holder S-BH U 75 M SDS	TE 2-A22, TE 4-A22, TE 6-A36	306013
	Dust removal system TE DRS-6-A cas	TE 6-A36	2040913
	Belt hook SF / SI	SFC 14-A, SIW 14-A, SFH 22-A, SIW 22T-A	2012703
	Charging adapter CA-B12	SF 2-A, SFD 2-A, SID 2-A	2077005
	Toolbag small	All Cordless tools	434910

